



Thermo Scientific FinnpiPETTE  
Manual Pipetting Systems


you can handle  
**anything**

**Thermo**  
SCIENTIFIC

# Leader in Pipetting Technology

Since the introduction of the first variable volume micropipette in 1971, more than **four million** Thermo Scientific™ pipettes have been sold in 150 countries. During this time, our goal has been to listen to customer feedback to develop a wide variety of modern models designed to improve precision and accuracy while remaining increasingly comfortable and easy to use.

## State-of-the-Art Features

- ▶ **Advanced Volume Gearing Mechanism** – Volume selection is more precise and controlled due to exact increment dialing
- ▶ **Supportive Finger Rest** – The wide hook rests comfortably in your hand reducing fatigue during pipetting cycles
- ▶ **Light Pipetting Action** – Smooth and steady action requires minimal effort and reduces the risk of Repetitive Strain Injury (RSI)
- ▶ **Large ErgoVision Display** – Easily view your volume setting
- ▶ **Customizable ID Tag** – Keep track of your pipettes for specific application or operator use
- ▶ **5 Year Warranty** – With convenient online registration 
- ▶ **CE Marked** – Optimized for use with Thermo Scientific™ Finntips™ in accordance with the IVD Directive in Europe
- ▶ **Color-coding** – Easily and quickly identify the correct volume Finntip

## History of Innovation


- ▶ **First** variable volume pipette
- ▶ **First** multichannel pipette
- ▶ **First** electronic trigger-action multichannel pipette
- ▶ **First** 16 channel pipette
- ▶ **First** expandable spacing pipette
- ▶ **First** electronic pipetting tracking device
- ▶ **First** self sealing filter barrier tips
- ▶ **First** extended length pipette tips
- ▶ **First** Thermo Scientific™ ClipTip™ pipette tip to lock on a pipette

# Achieve the Best Possible Performance

## Microliters Matter


Researchers are required to screen higher with the use of smaller quantities of precious compounds and expensive reagents per assay. This demands the use of pipettes that can meet the requirements of low volume pipetting while maintaining precision.

Specifically designed for micro-volume pipetting, the Thermo Scientific™ Finnpiquette™ **Super Blow-out Technology** provides a 150% increased air boost to ensure efficient delivery of micro-volumes while compensating for capillary action in 50 µl models and below.

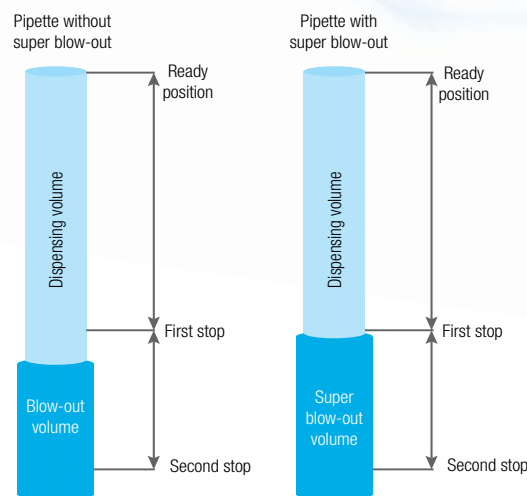

## Ergonomic Comfort

Designed to fit your hand and provide optimum comfort, the Finnpiquette **Soft-touch Tip Ejection** is a unique feature. An innovative gearing mechanism produces more down force with less effort, releasing Finntip pipette tips with just a gentle push. When used with multichannel pipettes, this innovative feature makes tip ejection easier than ever.

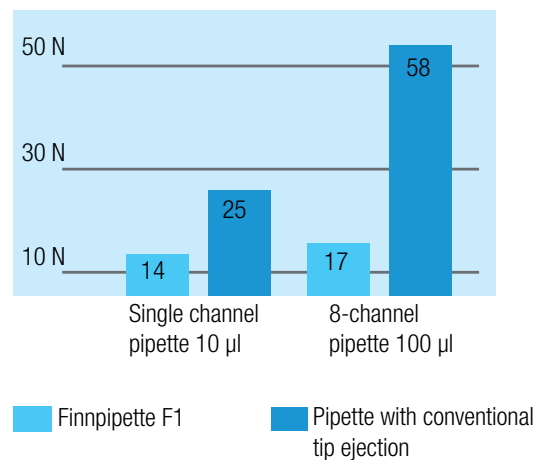

Legend: Finnpiquette F1 (light blue), Pipette with conventional tip ejection (dark blue)



# The Choice is Yours

## Thermo Scientific Finnpipette F1

The remarkably lightweight design combined with low attachment, ejection and plunger forces make pipetting with the Finnpipette F1 safe and comfortable. The adjustable finger rest rotates up to 120° making it ideal for both right- and left-handed users. Combined with its wide shape, the supportive hook rests comfortably in your hand reducing fatigue during pipetting cycles. The modern volume lock design ensures your selected volume will be locked safely in place to avoid accidental volume drift during pipetting cycles.

Low pipetting action reduces the risk of Repetitive Strain Injury (RSI) and enhances pipetting safety. The Finnpipette F1 provides superior accuracy and precision for performance you can rely on.



***Ergonomics, Safety,  
Performance***





## Thermo Scientific Finnpipette F2

To meet the needs of daily pipetting, the Finnpipette F2 is your choice. The durable construction exhibits excellent strength in a variety of challenging applications and environments. The pipette is fully autoclavable at 121°C and the black surface allows the Finnpipette F2 to withstand UV exposure without damage. Long-lasting materials enable extended product life in heavy-duty applications.



***Robust and Durable***

## Thermo Scientific Finntip Pipette Tips

### **A Pipette is only as Good as its Tip**





























Finntips are designed, developed and manufactured to perfectly fit Thermo Scientific Finnpipettes. A pipette's performance is directly related to the quality of the pipette tip—a pipette is only as good as its tip. This system provides optimal liquid handling results.

- Designed and manufactured according to ISO 9001, ISO 14001 and ISO 13485, Finntips are optimized for use with Finnpipettes and are CE/IVD Certified as a pipetting system.
- Finntips ensure the precision and accuracy of Finnpipettes while providing an ergonomic solution, reducing the tip attachment and ejection forces.
- All packaging designs color coordinate with Finnpipettes.
- Environmentally-friendly refill systems are compact, saving space and eliminating waste.




# Thermo Scientific Finn timer F1 and Finntip Pipette Tips

	10 µl
	20 µl/50 µl Micro
	200 µl
	300 µl
	1000 µl
	5 ml
	10 ml

Item No.	Description	Color Key	Volume Range	Increment/Packaging
<b>2 µl/10 µl PIPETTES</b>				<b>Increment</b>
4641010	Finn pipette F1, 0.2-2 µl		0.2-2 µl	0.002 µl
4641020	Finn pipette F1, 0.5-5 µl		0.5-5 µl	0.01 µl
4641030	Finn pipette F1, 1-10 µl		1-10 µl	0.02 µl
4661000	Finn pipette F1, 8-ch, 1-10 µl		1-10 µl	0.02 µl
4661040	Finn pipette F1, 12-ch, 1-10 µl		1-10 µl	0.02 µl
<b>10 µl FINNTIPS</b>				<b>Packaging</b>
9400310	Finntip 10		0.2-10 µl	Bulk, 1000 tips/bag
9400300	Finntip 10		0.2-10 µl	Racked, 96 tips/rack, 10 racks/pack
9400303	Finntip 10		0.2-10 µl	Racked, Sterile, 96 tips/rack, 10 racks/pack
9400326	Finntip 10		0.2-10 µl	Refill Kit, 192 tips/rack, 4 racks/kit, 192 tips/refill insert, 10 refill inserts/kit
9400327	Finntip 10		0.2-10 µl	Refill, 192 tips/refill insert, 20 refill inserts/pack
94052000	Finntip 10		0.2-10 µl	Racked, Filtered, Sterile, Micro, 96 tips/rack, 10 racks/pack
<b>20 µl/50 µl MICRO PIPETTES</b>				<b>Increment</b>
4661080	Finn pipette F1, 16-ch, 1-10 µl		1-10 µl	0.02 µl
4641050	Finn pipette F1, 2-20 µl		2-20 µl	0.02 µl
4641130	Finn pipette F1, 5-50 µl		5-50 µl	0.1 µl
4661090	Finn pipette F1, 16-ch, 5-50 µl		5-50 µl	0.1 µl
<b>20 µl/50 µl FINNTIPS, MICRO, 384-STYLE TIPS</b>				<b>Packaging</b>
9400620	Finntip 20		0.2-20 µl	Bulk, 1000 tips/bag
9400610	Finntip 20		0.2-20 µl	Racked, 384 tips/rack, 10 racks/pack
9400613	Finntip 20		0.2-20 µl	Racked, Sterile, 384 tips/rack, 10 racks/pack
94052020	Finntip 20		0.2-20 µl	Racked, Filtered, Sterile, Micro, 384 tips/rack, 10 racks/pack
9400360	Finntip 50		0.2-50 µl	Bulk, 1000 tips/bag
9400370	Finntip 50		0.2-50 µl	Racked, 384 tips/rack, 10 racks/pack
9400373	Finntip 50		0.2-50 µl	Racked, Sterile, 384 tips/rack, 10 racks/pack
94052060	Finntip 50		0.2-50 µl	Racked, Filtered, Sterile, Micro, 384 tips/rack, 10 racks/pack
<b>10 µl/200 µl PIPETTES</b>				<b>Increment</b>
4641040	Finn pipette F1, 1-10 µl		1-10 µl	0.02 µl
4641060	Finn pipette F1, 2-20 µl		2-20 µl	0.02 µl
4641140	Finn pipette F1, 5-50 µl		5-50 µl	0.1 µl
4661010	Finn pipette F1, 8-ch, 5-50 µl		5-50 µl	0.1 µl
4661050	Finn pipette F1, 12-ch, 5-50 µl		5-50 µl	0.1 µl
4641070	Finn pipette F1, 10-100 µl		10-100 µl	0.2 µl
4661020	Finn pipette F1, 8-ch, 10-100 µl		10-100 µl	0.2 µl
4661060	Finn pipette F1, 12-ch, 10-100 µl		10-100 µl	0.2 µl
4641080	Finn pipette F1, 20-200 µl		20-200 µl	0.2 µl
<b>200 µl/250 µl FINNTIPS</b>				<b>Packaging</b>
9400100	Finntip 200		5-200 µl	Bulk, 400 tips/box
9400130	Finntip 200		5-200 µl	Racked, Extended Length, 96 tips/rack, 10 racks/pack
9400133	Finntip 200		5-200 µl	Racked, Sterile, Extended Length, 96 tips/rack, 10 racks/pack
94052320	Finntip 200		5-200 µl	Racked, Filtered, Sterile, Extended Length, 96 tips/rack, 10 racks/pack
94052300	Finntip 200		0.5-200 µl	Racked, Filtered, Sterile, 96 tips/rack, 10 racks/pack
9400230	Finntip 250		0.5-250 µl	Bulk, 1000 tips/bag
9400260	Finntip 250		0.5-250 µl	Racked, 96 tips/rack, 10 racks/pack
9400263	Finntip 250		0.5-250 µl	Racked, Sterile, 96 tips/rack, 10 racks/pack
9400266	Finntip 250		0.5-250 µl	Refill Starter Kit, 96 tips/rack, 4 racks/kit, 96 tips/refill insert, 10 refill inserts/kit
9400267	Finntip 250		0.5-250 µl	Refill, 192 tips/refill insert, 20 refill inserts/pack

300 µl PIPETTES				Increment
4641090	Finnpipette F1, 30-300 µl	●	30-300 µl	1 µl
4661030	Finnpipette F1, 8-ch, 30-300 µl	●	30-300 µl	1 µl
4661070	Finnpipette F1, 12-ch, 30-300 µl	●	30-300 µl	1 µl
300 µl FINNTIPS				Packaging
9401260	Finntip 300	●	5-300 µl	Bulk, 1000 tips/bag
9401250	Finntip 300	●	5-300 µl	Racked, 96 tips/rack, 10 racks/pack
9401253	Finntip 300	●	5-300 µl	Racked, Sterile, 96 tips/rack, 10 racks/pack
9401255	Finntip 300	●	5-300 µl	Refill, 192 tips/refill insert, 20 refill inserts/pack
94052350	Finntip 300	●	5-300 µl	Racked, Filtered, Sterile, 96 tips/rack, 10 racks/pack
1000 µl PIPETTE				Increment
4641100	Finnpipette F1, 100-1000 µl	●	100-1000 µl	1 µl
1000 µl FINNTIPS				Packaging
9401410	Finntip 1000	●	100-1000 µl	Bulk, Extended Length, 1000 tips/bag
9401420	Finntip 1000	●	100-1000 µl	Racked, Extended Length, 96 tips/rack, 5 racks/pack
9401423	Finntip 1000	●	100-1000 µl	Racked, Sterile, Extended Length, 96 tips/rack, 5 racks/pack
94052430	Finntip 1000	●	100-1000 µl	Racked, Filtered, Sterile, Extended Length, 96 tips/rack, 5 racks/pack
9401030	Finntip 1000	●	100-1000 µl	Bulk, 1000 tips/bag
9401110	Finntip 1000	●	100-1000 µl	Racked, 96 tips/rack, 10 racks/pack
9401113	Finntip 1000	●	100-1000 µl	Racked, Sterile, 96 tips/rack, 10 racks/pack
9401115	Finntip 1000	●	100-1000 µl	Refill, 96 tips/refill insert, 10 refill inserts/pack
94052410	Finntip 1000	●	100-1000 µl	Racked, Filtered, Sterile, 96 tips/rack, 10 racks/pack
5 ml PIPETTE				Increment
4641110	Finnpipette F1, 0.5-5 ml	●	0.5-5 ml	0.01 ml
5 ml FINNTIPS				Packaging
9402030	Finntip 5 ml	●	0.5-5 ml	Bulk, 500 tips/bag
9402070	Finntip 5 ml	●	0.5-5 ml	Racked, 54 tips/rack, 5 racks/pack
9402073	Finntip 5 ml, sterile	●	0.5-5 ml	Racked, Sterile, 54 tips/rack, 5 racks/pack
94052550	Finntip Filter 5 ml, sterile	●	0.5-5 ml	Racked, Filtered, Sterile, 54 tips/rack, 5 racks/pack
10 ml PIPETTE				Increment
4641120	Finnpipette F1, 1-10 ml	●	1-10 ml	0.02 ml
10 ml FINNTIPS				Packaging
9402151	Finntip 10 ml	●	1-10 ml	Bulk, 100 tips/bag
9402160	Finntip 10 ml	●	1-10 ml	Racked, 24 tips/rack, 5 racks/pack
9402163	Finntip 10 ml, sterile	●	1-10 ml	Racked, Sterile, 24 tips/rack, 5 racks/pack
94052600	Finntip Filter 10 ml, sterile	●	1-10 ml	Racked, Filtered, Sterile, 24 tips/rack, 5 racks/pack

▶ Go to [thermoscientific.com](https://www.thermoscientific.com) for additional specifications for the Finnpipette F1 pipettes or the Finntip pipette tips.

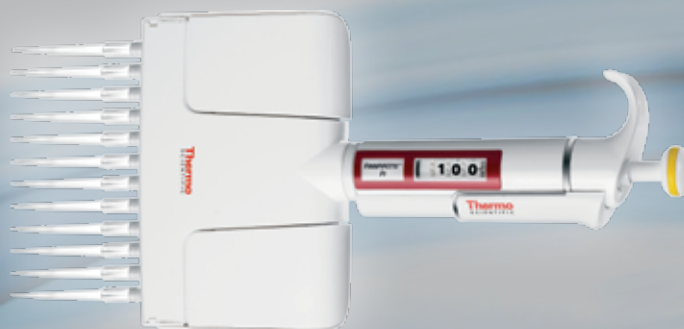

# Thermo Scientific Finn timer F2 and Finntip Pipette Tips

- 10  $\mu$ l
- 20  $\mu$ l/50  $\mu$ l Micro
- 200  $\mu$ l
- 300  $\mu$ l
- 1000  $\mu$ l
- 5 ml
- 10 ml

Item No.	Description	Color Key	Volume Range	Increment/Packaging
<b>2 <math>\mu</math>l/10 <math>\mu</math>l PIPETTES</b>				<b>Increment</b>
4642010	Finn pipette F2, 0.2-2 $\mu$ l	<span style="color: #ff69b4;">●</span>	0.2-2 $\mu$ l	0.002 $\mu$ l
4642020	Finn pipette F2, 0.5-5 $\mu$ l	<span style="color: #ff69b4;">●</span>	0.5-5 $\mu$ l	0.01 $\mu$ l
4642030	Finn pipette F2, 1-10 $\mu$ l	<span style="color: #ff69b4;">●</span>	1-10 $\mu$ l	0.02 $\mu$ l
4662000	Finn pipette F2, 8-ch, 1-10 $\mu$ l	<span style="color: #ff69b4;">●</span>	1-10 $\mu$ l	0.02 $\mu$ l
4662040	Finn pipette F2, 12-ch, 1-10 $\mu$ l	<span style="color: #ff69b4;">●</span>	1-10 $\mu$ l	0.02 $\mu$ l
<b>10 <math>\mu</math>l FINNTIPS</b>				<b>Packaging</b>
9400310	Finntip 10	<span style="color: #ff69b4;">●</span>	0.2-10 $\mu$ l	Bulk, 1000 tips/bag
9400300	Finntip 10	<span style="color: #ff69b4;">●</span>	0.2-10 $\mu$ l	Racked, 96 tips/rack, 10 racks/pack
9400303	Finntip 10	<span style="color: #ff69b4;">●</span>	0.2-10 $\mu$ l	Racked, Sterile, 96 tips/rack, 10 racks/pack
9400326	Finntip 10	<span style="color: #ff69b4;">●</span>	0.2-10 $\mu$ l	Refill Kit, 192 tips/rack, 4 racks/kit, 192 tips/refill insert, 10 refill inserts/kit
9400327	Finntip 10	<span style="color: #ff69b4;">●</span>	0.2-10 $\mu$ l	Refill, 192 tips/refill insert, 20 refill inserts/pack
94052000	Finntip 10	<span style="color: #ff69b4;">●</span>	0.2-10 $\mu$ l	Racked, Filtered, Sterile, Micro, 96 tips/rack, 10 racks/pack
<b>20 <math>\mu</math>l/50 <math>\mu</math>l MICRO PIPETTES</b>				<b>Increment</b>
4662080	Finn pipette F2, 16-ch, 1-10 $\mu$ l	<span style="color: #4169e1;">●</span> <span style="color: #4169e1;">●</span>	1-10 $\mu$ l	0.02 $\mu$ l
4642050	Finn pipette F2, 2-20 $\mu$ l	<span style="color: #4169e1;">●</span> <span style="color: #4169e1;">●</span>	2-20 $\mu$ l	0.02 $\mu$ l
4642120	Finn pipette F2, 5-50 $\mu$ l	<span style="color: #4169e1;">●</span>	5-50 $\mu$ l	0.1 $\mu$ l
4662090	Finn pipette F2, 16-ch, 5-50 $\mu$ l	<span style="color: #4169e1;">●</span>	5-50 $\mu$ l	0.1 $\mu$ l
<b>20 <math>\mu</math>l/50 <math>\mu</math>l FINNTIPS, MICRO, 384-STYLE TIPS</b>				<b>Packaging</b>
9400620	Finntip 20	<span style="color: #4169e1;">●</span>	0.2-20 $\mu$ l	Bulk, 1000 tips/bag
9400610	Finntip 20	<span style="color: #4169e1;">●</span>	0.2-20 $\mu$ l	Racked, 384 tips/rack, 10 racks/pack
9400613	Finntip 20	<span style="color: #4169e1;">●</span>	0.2-20 $\mu$ l	Racked, Sterile, 384 tips/rack, 10 racks/pack
94052020	Finntip 20	<span style="color: #4169e1;">●</span>	0.2-20 $\mu$ l	Racked, Filtered, Sterile, Micro, 384 tips/rack, 10 racks/pack
9400360	Finntip 50	<span style="color: #4169e1;">●</span>	0.2-50 $\mu$ l	Bulk, 1000 tips/bag
9400370	Finntip 50	<span style="color: #4169e1;">●</span>	0.2-50 $\mu$ l	Racked, 384 tips/rack, 10 racks/pack
9400373	Finntip 50	<span style="color: #4169e1;">●</span>	0.2-50 $\mu$ l	Racked, Sterile, 384 tips/rack, 10 racks/pack
94052060	Finntip 50	<span style="color: #4169e1;">●</span>	0.2-50 $\mu$ l	Racked, Filtered, Sterile, Micro, 384 tips/rack, 10 racks/pack
<b>10 <math>\mu</math>l/200 <math>\mu</math>l PIPETTES</b>				<b>Increment</b>
4642040	Finn pipette F2, 1-10 $\mu$ l	<span style="color: #ffff00;">●</span>	1-10 $\mu$ l	0.02 $\mu$ l
4642060	Finn pipette F2, 2-20 $\mu$ l	<span style="color: #ffff00;">●</span>	2-20 $\mu$ l	0.02 $\mu$ l
4642130	Finn pipette F2, 5-50 $\mu$ l	<span style="color: #ffff00;">●</span>	5-50 $\mu$ l	0.1 $\mu$ l
4662010	Finn pipette F2, 8-ch, 5-50 $\mu$ l	<span style="color: #ffff00;">●</span>	5-50 $\mu$ l	0.1 $\mu$ l
4662050	Finn pipette F2, 12-ch, 5-50 $\mu$ l	<span style="color: #ffff00;">●</span>	5-50 $\mu$ l	0.1 $\mu$ l
4642070	Finn pipette F2, 10-100 $\mu$ l	<span style="color: #ffff00;">●</span>	10-100 $\mu$ l	0.2 $\mu$ l
4662020	Finn pipette F2, 8-ch, 10-100 $\mu$ l	<span style="color: #ffff00;">●</span>	10-100 $\mu$ l	0.2 $\mu$ l
4662060	Finn pipette F2, 12-ch, 10-100 $\mu$ l	<span style="color: #ffff00;">●</span>	10-100 $\mu$ l	0.2 $\mu$ l
4642080	Finn pipette F2, 20-200 $\mu$ l	<span style="color: #ffff00;">●</span>	20-200 $\mu$ l	0.2 $\mu$ l
<b>200 <math>\mu</math>l/250 <math>\mu</math>l FINNTIPS</b>				<b>Packaging</b>
9400100	Finntip 200	<span style="color: #ffff00;">●</span>	5-200 $\mu$ l	Bulk, 400 tips/box
9400130	Finntip 200	<span style="color: #ffff00;">●</span>	5-200 $\mu$ l	Racked, Extended Length, 96 tips/rack, 10 racks/pack
9400133	Finntip 200	<span style="color: #ffff00;">●</span>	5-200 $\mu$ l	Racked, Sterile, Extended Length, 96 tips/rack, 10 racks/pack
94052320	Finntip 200	<span style="color: #ffff00;">●</span>	5-200 $\mu$ l	Racked, Filtered, Sterile, Extended Length, 96 tips/rack, 10 racks/pack
94052300	Finntip 200	<span style="color: #ffff00;">●</span>	0.5-200 $\mu$ l	Racked, Filtered, Sterile, 96 tips/rack, 10 racks/pack
9400230	Finntip 250	<span style="color: #ffff00;">●</span>	0.5-250 $\mu$ l	Bulk, 1000 tips/bag
9400260	Finntip 250	<span style="color: #ffff00;">●</span>	0.5-250 $\mu$ l	Racked, 96 tips/rack, 10 racks/pack
9400263	Finntip 250	<span style="color: #ffff00;">●</span>	0.5-250 $\mu$ l	Racked, Sterile, 96 tips/rack, 10 racks/pack
9400266	Finntip 250	<span style="color: #ffff00;">●</span>	0.5-250 $\mu$ l	Refill Starter Kit, 96 tips/rack, 4 racks/kit, 96 tips/refill insert, 10 refill inserts/kit
9400267	Finntip 250	<span style="color: #ffff00;">●</span>	0.5-250 $\mu$ l	Refill, 192 tips/refill insert, 20 refill inserts/pack



300 µl PIPETTES				Increment
4662030	Finnpipette F2, 8-ch 30-300 µl	●	30-300 µl	1 µl
4662070	Finnpipette F2, 12-ch 30-300 µl	●	30-300 µl	1 µl
300 µl FINNTIPS				Packaging
9401260	Finntip 300	●	5-300 µl	Bulk, 1000 tips/bag
9401250	Finntip 300	●	5-300 µl	Racked, 96 tips/rack, 10 racks/pack
9401253	Finntip 300	●	5-300 µl	Racked, Sterile, 96 tips/rack, 10 racks/pack
9401255	Finntip 300	●	5-300 µl	Refill, 192 tips/refill insert, 20 refill inserts/pack
94052350	Finntip 300	●	5-300 µl	Racked, Filtered, Sterile, 96 tips/rack, 10 racks/pack
1000 µl PIPETTE				Increment
4642090	Finnpipette F2, 100-1000 µl	●	100-1000 µl	1 µl
1000 µl FINNTIPS				Packaging
9401410	Finntip 1000	●	100-1000 µl	Bulk, Extended Length, 1000 tips/bag
9401420	Finntip 1000	●	100-1000 µl	Racked, Extended Length, 96 tips/rack, 5 racks/pack
9401423	Finntip 1000	●	100-1000 µl	Racked, Sterile, Extended Length, 96 tips/rack, 5 racks/pack
94052430	Finntip 1000	●	100-1000 µl	Racked, Filtered, Sterile, Extended Length, 96 tips/rack, 5 racks/pack
9401030	Finntip 1000	●	100-1000 µl	Bulk, 1000 tips/bag
9401110	Finntip 1000	●	100-1000 µl	Racked, 96 tips/rack, 10 racks/pack
9401113	Finntip 1000	●	100-1000 µl	Racked, Sterile, 96 tips/rack, 10 racks/pack
9401115	Finntip 1000	●	100-1000 µl	Refill, 96 tips/refill insert, 10 refill inserts/pack
94052410	Finntip 1000	●	100-1000 µl	Racked, Filtered, Sterile, 96 tips/rack, 10 racks/pack
5 ml PIPETTE				Increment
4642100	Finnpipette F2, 0.5-5 ml	●	0.5-5 ml	0.01 ml
5 ml FINNTIPS				Packaging
9402030	Finntip 5 ml	●	0.5-5 ml	Bulk, 500 tips/bag
9402070	Finntip 5 ml	●	0.5-5 ml	Racked, 54 tips/rack, 5 racks/pack
9402073	Finntip 5 ml, sterile	●	0.5-5 ml	Racked, Sterile, 54 tips/rack, 5 racks/pack
94052550	Finntip Filter 5 ml, sterile	●	0.5-5 ml	Racked, Filtered, Sterile, 54 tips/rack, 5 racks/pack
10 ml PIPETTE				Increment
4642110	Finnpipette F2, 1-10 ml	●	1-10 ml	0.02 ml
10 ml FINNTIPS				Packaging
9402151	Finntip 10 ml	●	1-10 ml	Bulk, 100 tips/bag
9402160	Finntip 10 ml	●	1-10 ml	Racked, 24 tips/rack, 5 racks/pack
9402163	Finntip 10 ml, sterile	●	1-10 ml	Racked, Sterile, 24 tips/rack, 5 racks/pack
94052600	Finntip Filter 10 ml, sterile	●	1-10 ml	Racked, Filtered, Sterile, 24 tips/rack, 5 racks/pack

▶ Go to [thermoscientific.com](http://thermoscientific.com) for additional specifications for the Finn timer F2 pipettes or the Finntip pipette tips.



# Fixed Volume Pipettes

## Finnpipette F1

Item No.	Description	Color Key	Volume Range
4651000	Finnpipette F1, 1 µl	●	1 µl
4651010	Finnpipette F1, 5 µl	●	5 µl
4651020	Finnpipette F1, 10 µl	●	10 µl
4651130	Finnpipette F1, 20 µl	●	20 µl
4651030	Finnpipette F1, 25 µl	●	25 µl
4651040	Finnpipette F1, 50 µl	●	50 µl
4651050	Finnpipette F1, 100 µl	●	100 µl
4651140	Finnpipette F1, 200 µl	●	200 µl
4651060	Finnpipette F1, 250 µl	●	250 µl
4651070	Finnpipette F1, 500 µl	●	500 µl
4651080	Finnpipette F1, 1000 µl	●	1000 µl
4651090	Finnpipette F1, 2000 µl	●	2000 µl
4651100	Finnpipette F1, 3000 µl	●	3000 µl
4651110	Finnpipette F1, 5000 µl	●	5000 µl
4651120	Finnpipette F1, 10000 µl	●	10000 µl

## Finnpipette F2

Item No.	Description	Color Key	Volume Range
4652000	Finnpipette F2, 1 µl	●	1 µl
4652010	Finnpipette F2, 5 µl	●	5 µl
4652020	Finnpipette F2, 10 µl	●	10 µl
4652130	Finnpipette F2, 20 µl	●	20 µl
4652030	Finnpipette F2, 25 µl	●	25 µl
4652040	Finnpipette F2, 50 µl	●	50 µl
4652050	Finnpipette F2, 100 µl	●	100 µl
4652140	Finnpipette F2, 200 µl	●	200 µl
4652060	Finnpipette F2, 250 µl	●	250 µl
4652070	Finnpipette F2, 500 µl	●	500 µl
4652080	Finnpipette F2, 1000 µl	●	1000 µl
4652090	Finnpipette F2, 2000 µl	●	2000 µl
4652100	Finnpipette F2, 3000 µl	●	3000 µl
4652110	Finnpipette F2, 5000 µl	●	5000 µl
4652120	Finnpipette F2, 10000 µl	●	10000 µl

# Good Laboratory Pipetting Kits

## Finnpipette F1

Item No.	Description	Contents of Kit
4700850	<b>Finnpipette F1 GLP Kit 1</b>	<ul style="list-style-type: none"> <li>• Finnpipette F1 1-10 µl single channel</li> <li>• Finnpipette F1 10-100 µl single channel</li> <li>• Finnpipette F1 100-1000 µl single channel</li> <li>• F-Series Stand</li> <li>• 4 Racks of Finntip Flex tips</li> </ul>
4700860	<b>Finnpipette F1 GLP Kit 2</b>	<ul style="list-style-type: none"> <li>• Finnpipette F1 0.2-2 µl single channel</li> <li>• Finnpipette F1 2-20, 20-200 µl single channel</li> <li>• Finnpipette F1 100-1000 µl single channel</li> <li>• F-Series Stand</li> <li>• 4 Racks of Finntip Flex tips</li> </ul>
4700865	<b>Finnpipette F1 GLP Kit 3</b>	<ul style="list-style-type: none"> <li>• Finnpipette F1 10-100 µl single channel</li> <li>• Finnpipette F1 100-1000 µl single channel</li> <li>• Finnpipette F1 1-10 ml pipettes single channel</li> <li>• F-Series Stand</li> <li>• 4 Racks of Finntip/Finntip Flex</li> </ul>
4701060	<b>Finnpipette F1 GLP Kit 4</b>	<ul style="list-style-type: none"> <li>• Finnpipette F1 2-20 µl</li> <li>• Finnpipette F1 20-200 µl single channel</li> <li>• Finnpipette F1 100-1000 µl single channel</li> <li>• F-Series Stand</li> <li>• 3 Racks of Finntip Flex</li> </ul>




## Finnpipette F2

Item No.	Description	Contents of Kit
4700870	<b>Finnpipette F2 GLP Kit 1</b>	<ul style="list-style-type: none"> <li>• Finnpipette F2 1-10 µl single channel</li> <li>• Finnpipette F2 10-100 µl single channel</li> <li>• Finnpipette F2 100-1000 µl single channel</li> <li>• F-Series Stand</li> <li>• 4 Racks of Finntip Flex tips</li> </ul>
4700880	<b>Finnpipette F2 GLP Kit 2</b>	<ul style="list-style-type: none"> <li>• Finnpipette F2 0.2-2 µl single channel</li> <li>• Finnpipette F2 2-20, 20-200 µl single channel</li> <li>• Finnpipette F2 100-1000 µl single channel</li> <li>• F-Series Stand</li> <li>• Racks of Finntip Flex tips</li> </ul>
4700885	<b>Finnpipette F2 GLP Kit 3</b>	<ul style="list-style-type: none"> <li>• Finnpipette F2 10-100 µl single channel</li> <li>• Finnpipette F2 100-1000 µl single channel</li> <li>• Finnpipette F2 1-10 ml pipettes single channel</li> <li>• F-Series Stand</li> <li>• 4 Racks of Finntip/Finntip Flex</li> </ul>
4701070	<b>Finnpipette F2 GLP Kit 4</b>	<ul style="list-style-type: none"> <li>• Finnpipette F2 2-20 µl</li> <li>• Finnpipette F2 20-200 µl single channel</li> <li>• Finnpipette F2 100-1000 µl single channel</li> <li>• F-Series Stand</li> <li>• 3 Racks of Finntip Flex</li> </ul>



## Accessories

Item No.	Description
9510027	Reagent Basin, 60 ml
9510037	Reservoir, 8-well, 10 ml
9510047	Reservoir, 1-well, 100 ml
95128085	Reagent Reservoir, Disposable, 100 ml
95128095	Reagent Reservoir, Disposable, w/Divider, 25 ml
95128080	Reagent Reservoir Demo Package
95128093	Reagent Reservoir, Disposable, 25 ml
9420400	F-Series Stand, white, 6 positions
9420390	Multichannel Pipette Stand, 1 position
9420290	Pipette Stand, gray, 6 positions
9420320	Pipette Mini-stand, gray, 3 positions
9420340	Carousel Stand, for 6 manual or 3 electronic pipettes, includes cover

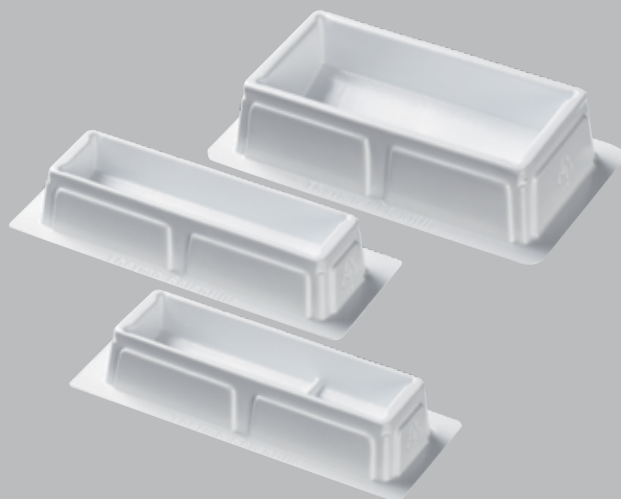

## Electronic Pipetting Systems

### Unity™ Lab Services

Part of Thermo Fisher Scientific

To improve your laboratory's efficiency, you should be free to focus on your work, not burdened with managing instrument service. We provide a complete portfolio of customized, integrated and innovative services and support solutions designed to help you improve productivity, reduce total cost of ownership and ensure compliance throughout your laboratory – from instrument and equipment acquisition to disposition. **Let our expertise complement yours.**

Learn more about our pipette service offerings at: [www.unitylabservice.com/pipette](http://www.unitylabservice.com/pipette)



A calibration report is included with every Finn timer pipette. While the pipettes don't need adjustment, they are constructed to permit easy adjustment of various temperature and viscosity liquids.

## Looking to relieve all thumb action?

Meet your new favorite pipette, the **Thermo Scientific Finn timer Novus Electronic pipette.**



## Need a boost in productivity?

Try **Thermo Scientific™ Matrix™ Electronic pipettes** to speed research in your laboratory.



### pipette extended warranty registration

Register your pipette online for a **Free** extended 5 year warranty  
[www.thermoscientific.com/pipetwarranty](http://www.thermoscientific.com/pipetwarranty)

© 2013 Thermo Fisher Scientific Inc. All rights reserved. All trademarks are the property of Thermo Fisher Scientific Inc. and its subsidiaries. Specifications, terms and pricing are subject to change. Not all products are available in all countries. Please consult your local sales representative for details.

[www.thermoscientific.com/liquidhandling](http://www.thermoscientific.com/liquidhandling)

**Australia** +61 39757 4300  
**Austria** +43 1 801 40 0  
**Belgium** +32 53 73 42 41  
**China** +86 21 6865 4588 or  
+86 10 8419 3588  
**France** +33 2 2803 2180  
**Germany national toll free** 0800 1 536 376  
**Germany international** +49 6184 90 6000

**India toll free** 1800 22 8374  
**India** +91 22 6716 2200  
**Italy** +39 02 95059 554  
**Japan** +81 45 453 9220  
**Netherlands** +31 76 579 55 55  
**New Zealand** +64 9 980 6700  
**Nordic/Baltic/CIS countries**  
+358 9 329 10200

**Russia** +7 812 703 42 15  
**Spain/Portugal** +34 93 223 09 18  
**Switzerland** +41 44 454 12 12  
**UK/Ireland** +44 870 609 9203  
**USA/Canada** +1 866 984 3766

**Other Asian countries** +852 2885 4613  
**Countries not listed** +49 6184 90 6000

Learn more about our liquid handling solutions, application notes, product specifications and videos at:  
[www.thermoscientific.com/handleanything](http://www.thermoscientific.com/handleanything)